

Part No: 1839V-010C

All

BV-1

Desc: 1 CPVC TU2KINDBV SOC/FPT FKM VENTED

MSRP: 216.02

Part Code: 602

Weight(lbs): 1.008

Weight(kg): 0.457


Weight(gm): 457

Size: 1

Color: GRAY

Material: CPVC

Connection Socket Ends FKM

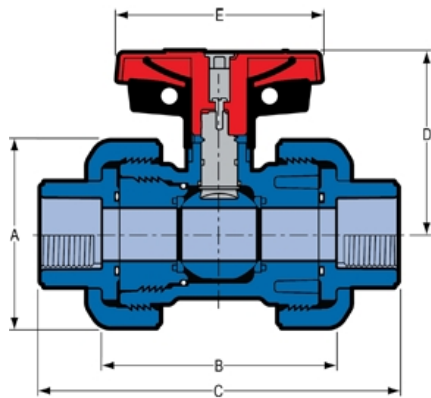

A = 2- 1/2

B = 2- 7/8

C = 5- 1/8

D = 3- 1/8

E = 3- 7/16

Cv = 120

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

