

Part No: 1880-170C

Nipples

Nipple

Desc: 1/4X17 CPVC NIPPLE TOE SCH80

MSRP: 28.86

Part Code: 121

Weight(lbs): 0.205

Weight(kg): 0.093

Weight(gm): 93


Size: 1/4" x 17"

Color: GRAY

Material: CPVC

Connection 1/4" Diameter

Nipple Type TOE (Plain x Mipt)

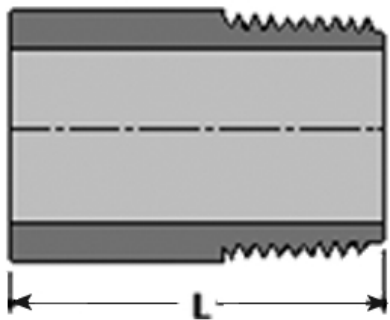

L = 17

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

