

**Part No:** 1884-060C

**Nipples**

**Nipple**

**Desc:** 1X6 CPVC NIPPLE TOE SCH80

**MSRP:** 13.99

**Part Code:** 121

**Weight(lbs):** 0.225

**Weight(kg):** 0.102


**Weight(gm):** 102

**Size:** 1" x 6"

**Color:** GRAY

**Material:** CPVC

**Nipple Type** TOE (Plain x Mipt)

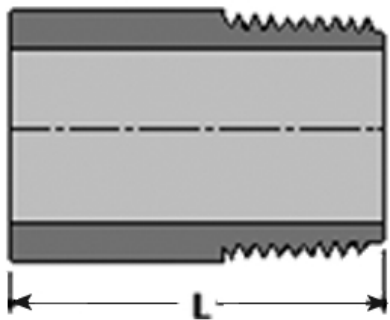

**L = 6**

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  inch & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

