

Part No: 1886-055C

Nipples

Nipple

Desc: 1-1/2X5-1/2 CPVC NIPPLE TOE SCH80

MSRP: 25.7

Part Code: 121

Weight(lbs): 0.375

Weight(kg): 0.17


Weight(gm): 170

Size: 1-1/2" x 5-1/2"

Color: GRAY

Material: CPVC

Nipple Type TOE (Plain x Mipt)

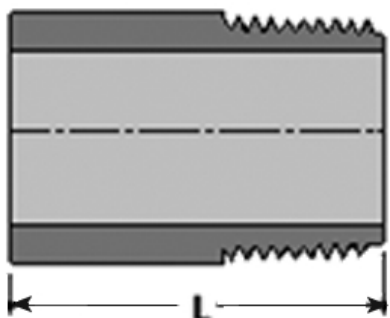

L = 5-1/2

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

