

**Part No:** 1893-005

**Nipples**

**Nipple**

**Desc:** 8XCL PVC NIPPLE TOE SCH80

**MSRP:** 72.2

**Part Code:** 120

**Weight(lbs):** 4.264

**Weight(kg):** 1.934


**Weight(gm):** 1934

**Size:** 8" x CL

**Color:** GRAY

**Material:** PVC

**Nipple Type** TOE (Plain x Mipt)

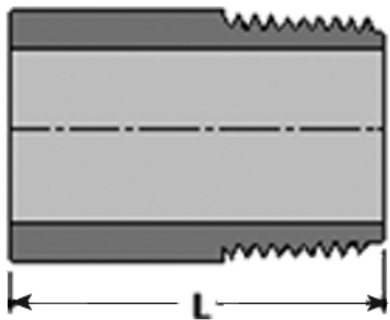

**L** = 1/2

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

