

Part No: 2011-040CSR

Valves

Gate Valve

Desc: 4 CPVC GATE VALVE W/SS RING THD BUNA

MSRP: 2817.07

Part Code: 203

Weight(lbs): 14.548

Weight(kg): 6.599

Weight(gm): 6599


Size: 4"

Color: GRAY

Material: CPVC

Connection SR Fipt

O-Ring Buna-N

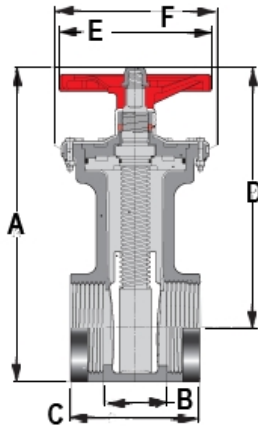

A = 16- 3/8

B = 3- 1/8

C = 7- 7/8

D = 13-19/32

E = 7- 7/8

F = 7- 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

