

**Part No:** 2013-010C

**Valves**

**Gate Valve**

**Desc:** 1 CPVC GATE VALVE FLANGED BUNA

**MSRP:** 631.24

**Part Code:** 202

**Weight(lbs):** 1.528

**Weight(kg):** 0.693

**Weight(gm):** 693


**Size:** 1"

**Color:** GRAY

**Material:** CPVC

**Connection** Flanged

**O-Ring** Buna-N

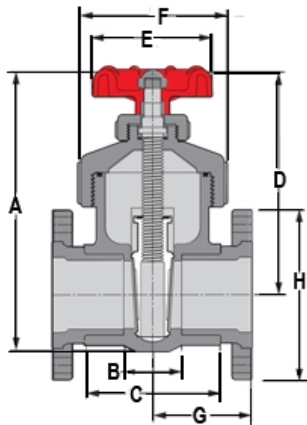

**A** = 5-13/32

**B** = 1- 1/4

**C** = 3-1/4

**D** = 4- 5/16

**E** = 2- 5/8

**F** = 2-15/16

**G** = 2-11/16

**Cv** = 39  
**Values**

**G** = 2-11/16

**H** = 4-1/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

