

Part No: 2013-012C

Valves

Gate Valve

Desc: 1-1/4 CPVC GATE VALVE FLANGED BUNA

MSRP: 853.78

Part Code: 202

Weight(lbs): 2.716

Weight(kg): 1.232

Weight(gm): 1232


Size: 1-1/4"

Color: GRAY

Material: CPVC

Connection Flanged

O-Ring Buna-N

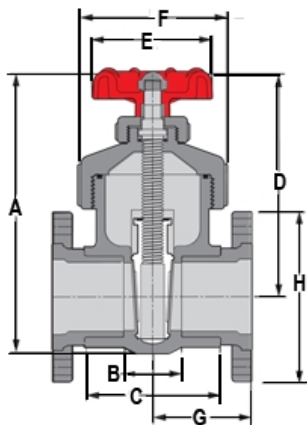

A = 8- 1/16

B = 1- 9/16

C = 3- 9/16

D = 6- 9/16

E = 3- 7/16

F = 3-15/16

G = 3

Cv = 105
Values

H = 4-5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

