

Part No: 2013-020C

Valves

Gate Valve

Desc: 2 CPVC GATE VALVE FLANGED BUNA

MSRP: 1079.86

Part Code: 202

Weight(lbs): 4.381

Weight(kg): 1.987

Weight(gm): 1987


Size: 2"

Color: GRAY

Material: CPVC

Connection Flanged

O-Ring Buna-N

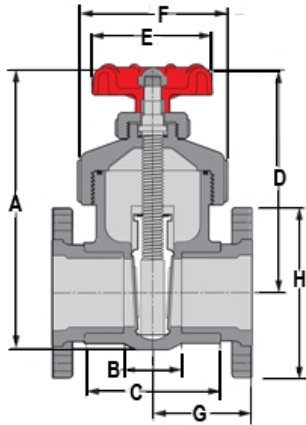

A = 8- 9/16

B = 1-11/16

C = 3-15/16

D = 6- 7/8

E = 3-15/16

F = 4- 7/16

H = 6

G = 3- 5/8

Cv = 279
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

