

Part No: 2233-012

Valves

Ball Check Valve

Desc: 1-1/4 PVC TU BALL CHECK VALVE FLGD FKM

MSRP: 334.66

Part Code: 220

Weight(lbs): 2.624

Weight(kg): 1.19

Weight(gm): 1190

Size: 1-1/4"


Color: GRAY

Material: PVC

Connection Flanged (Regular Style)

O-Ring FKM

Pressure Rating 150 psi @ 73° F

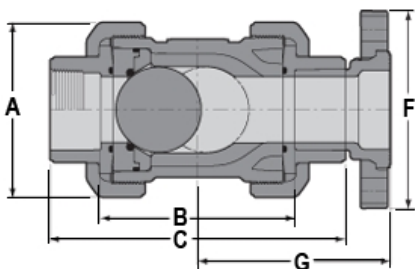

A = 3-11/16

B = 4- 1/2

C = 7

Cv = 142
Values

F = 4- 5/8

G = 4- 9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

