

Part No: 2321-025

Valves

True Union Ball Valve

Desc: 2-1/2 PVC TU BALL VALVE THD EPDM

MSRP: 397.54

Part Code: 230

Weight(lbs): 12.297

Weight(kg): 5.578

Weight(gm): 5578

Size: 2-1/2"

Color: GRAY


Material: PVC

Type True Union - Regular Style

O-Ring EPDM

Connection Fipt

Pressure Rating 150 psi @ 73° F

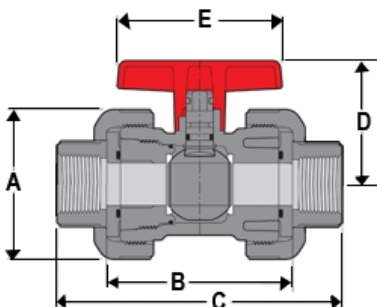

A = 7- 7/16

B = 8- 3/8

C = 11- 7/8

D = 4-29/32

E = 9- 7/8

Cv = 712

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

