

Part No: 2323-010C

Valves

True Union Ball Valve

Desc: 1 CPVC TU BALL VALVE FLANGED EPDM

MSRP: 302.29

Part Code: 232

Weight(lbs): 2.337

Weight(kg): 1.06

Weight(gm): 1060

Size: 1"

Color: GRAY


Material: CPVC

Type True Union - Regular Style

O-Ring EPDM

Connection Flanged

Pressure Rating 150 psi @ 73° F

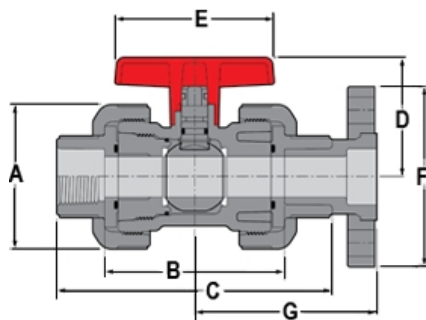

A = 3-13/32

B = 4- 5/16

C = 6- 9/16

D = 2-13/16

E = 3-23/32

F = 4- 1/4

G = 4- 5/16

Cv = 67
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

