

Part No: 2323-012C

Valves

True Union Ball Valve

Desc: 1-1/4 CPVC TU BALL VALVE FLANGED EPDM

MSRP: 451.6

Part Code: 232

Weight(lbs): 2.919

Weight(kg): 1.324

Weight(gm): 1324

Size: 1-1/4"

Color: GRAY


Material: CPVC

Type True Union - Regular Style

O-Ring EPDM

Connection Flanged

Pressure Rating 150 psi @ 73° F

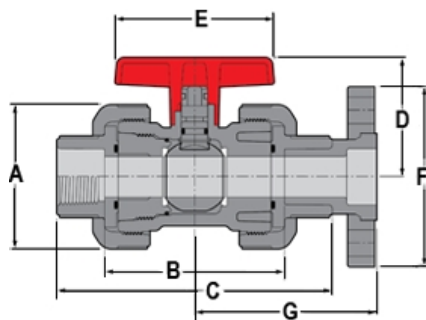

A = 3-11/16

B = 4- 1/2

C = 7- 1/16

D = 2-31/32

E = 4- 1/8

F = 4- 5/8

G = 4-19/32

Cv = 142

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

