

**Part No:** 2323-025

**Valves**

**True Union Ball Valve**

**Desc:** 2-1/2 PVC TU BALL VALVE FLANGED EPDM

**MSRP:** 870.87

**Part Code:** 230

**Weight(lbs):** 14.91

**Weight(kg):** 6.763

**Weight(gm):** 6763

**Size:** 2-1/2"

**Color:** GRAY


**Material:** PVC

**Type** True Union - Regular Style

**O-Ring** EPDM

**Connection** Flanged

**Pressure Rating** 150 psi @ 73° F

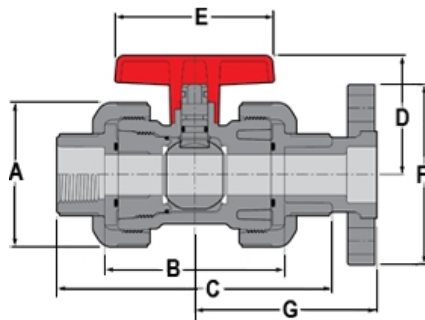

**A** = 7- 7/16

**B** = 8- 3/8

**C** = 11- 7/8

**D** = 4-29/32

**E** = 9- 7/8

**F** = 7

**G** = 7- 3/16

**Cv** = 512

**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

