

Part No: 2323-025C

Valves

True Union Ball Valve

Desc: 2-1/2 CPVC TU BALL VALVE FLANGED EPDM

MSRP: 1225.68

Part Code: 232

Weight(lbs): 15.953

Weight(kg): 7.236

Weight(gm): 7236

Size: 2-1/2"

Color: GRAY


Material: CPVC

Type True Union - Regular Style

O-Ring EPDM

Connection Flanged

Pressure Rating 150 psi @ 73° F

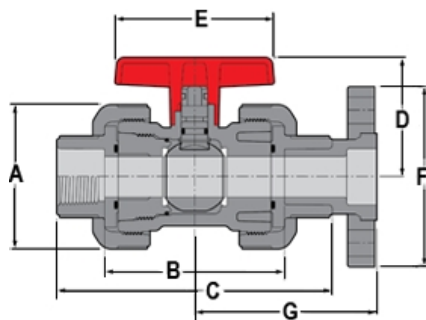

A = 7- 7/16

B = 8- 3/8

C = 11- 7/8

D = 4-29/32

E = 9- 7/8

F = 7

G = 7- 3/16

Cv = 512

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

