

Part No: 2329-015

Valves

True Union Ball Valve

Desc: 1-1/2 PVC TU BALL VALVE SOC/FPT EPDM

MSRP: 165.01

Part Code: 230

Weight(lbs): 3.34

Weight(kg): 1.515

Weight(gm): 1515

Size: 1-1/2"

Color: GRAY


Material: PVC

Type True Union - Regular Style

O-Ring EPDM

Connection Socket + Fipt

Pressure Rating 235 psi @ 73° F

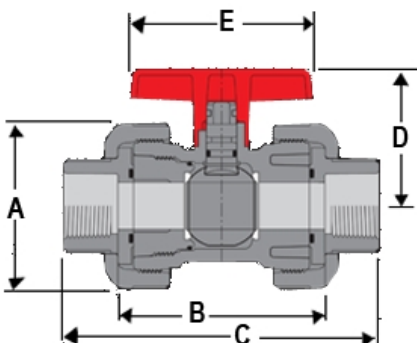

A = 4- 3/8

B = 5- 5/16

C = 8- 1/32

D = 3- 9/32

E = 4-15/32

Cv = 285

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

