

Part No: 2331-040

Valves

True Union Ball Valve

Desc: 4 PVC TU BALL VALVE THD FKM

MSRP: 1345.98

Part Code: 230

Weight(lbs): 18.757

Weight(kg): 8.508

Weight(gm): 8508

Size: 4"

Color: GRAY


Material: PVC

Type True Union - Regular Style

O-Ring FKM

Connection Fipt

Pressure Rating 150 psi @ 73° F

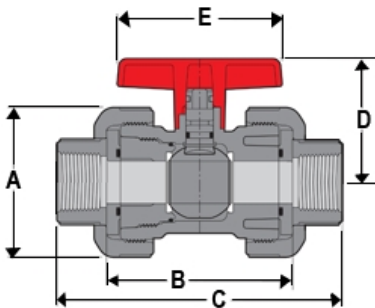

A = 8- 7/8

B = 8- 3/4

C = 13- 1/4

D = 6- 1/4

E = 10- 3/4

Cv = 2629

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

