

Part No: 2332-025C

Valves

True Union Ball Valve

Desc: 2-1/2 CPVC TU BALL VALVE SOC FKM

MSRP: 1011.4

Part Code: 232

Weight(lbs): 12.778

Weight(kg): 5.796

Weight(gm): 5796

Size: 2-1/2"

Color: GRAY


Material: CPVC

Type True Union - Regular Style

O-Ring FKM

Connection Socket

Pressure Rating 150 psi @ 73° F

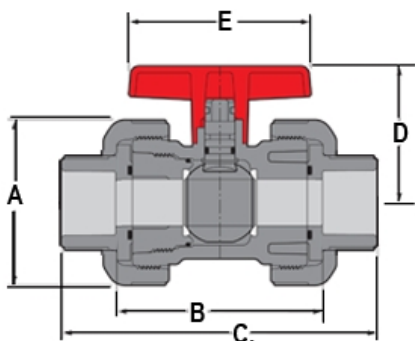

A = 7- 7/16

B = 8- 7/16

C = 11-15/16

D = 5-27/32

E = 9- 7/8

Cv = 712

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

