

Part No: 2332-040C

Valves

True Union Ball Valve

Desc: 4 CPVC TU BALL VALVE SOC FKM

MSRP: 2142.97

Part Code: 232

Weight(lbs): 19.31

Weight(kg): 8.759

Weight(gm): 8759

Size: 4"

Color: GRAY


Material: CPVC

Type True Union - Regular Style

O-Ring FKM

Connection Socket

Pressure Rating 150 psi @ 73° F

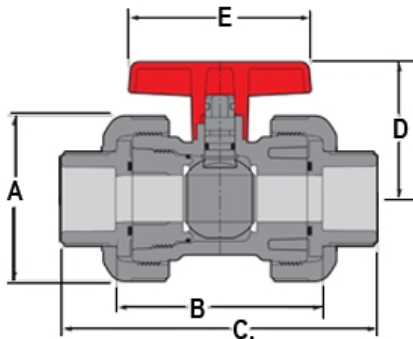

A = 8-15/16

B = 8-11/16

C = 13- 3/16

D = 5-19/32

E = 10-13/16

Cv = 2629

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

