

Part No: 2333-015C

Valves

True Union Ball Valve

Desc: 1-1/2 CPVC TU BALL VALVE FLANGED FKM

MSRP: 513.26

Part Code: 232

Weight(lbs): 4.317

Weight(kg): 1.958

Weight(gm): 1958

Size: 1-1/2"

Color: GRAY


Material: CPVC

Type True Union - Regular Style

O-Ring FKM

Connection Flanged

Pressure Rating 150 psi @ 73° F

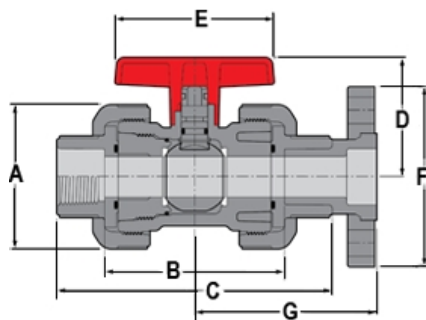

A = 4- 3/8

B = 5- 5/16

C = 8- 1/32

D = 3- 9/32

E = 4-15/32

F = 5

G = 5- 9/32

Cv = 201

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

