

Part No: 2333-020C

Valves

True Union Ball Valve

Desc: 2 CPVC TU BALL VALVE FLANGED FKM

MSRP: 823.27

Part Code: 232

Weight(lbs): 6.537

Weight(kg): 2.965

Weight(gm): 2965

Size: 2"

Color: GRAY


Material: CPVC

Type True Union - Regular Style

O-Ring FKM

Connection Flanged

Pressure Rating 150 psi @ 73° F

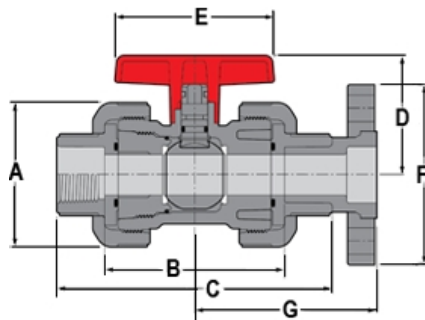

A = 5- 3/16

B = 5-13/16

C = 8-13/16

D = 4-13/32

E = 5- 1/4

F = 6

G = 5-23/32

Cv = 381

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

