

Part No: 2333-060C

Valves

True Union Ball Valve

Desc: 6 CPVC TU BALL VALVE FLG FKM VENTURIED

MSRP: 5041.73

Part Code: 233

Weight(lbs): 34.381


Weight(kg): 15.595

Weight(gm): 15595

Size: 6"

Color: GRAY

Material: CPVC

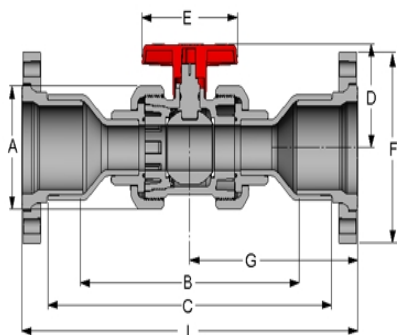

Type True Union - Regular Style
O-Ring FKM
Connection Flanged
Pressure Rating 150 psi @ 73° F

A = 8-15/16

B = 18-5/8

C = 26-1/8

D = 6- 3/4

E = 10-13/16

F = 11- 1/4

G = 14-11/16

L = 29-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

