

Part No: 2411-005G

Valves

Single Entry Ball Valve

Desc: 1/2 PVC SE BALL VALVE THD BUNA

MSRP: 35.08

Part Code: 240

Weight(lbs): 0.231


Weight(kg): 0.105

Weight(gm): 105

Size: 1/2"

Color: GRAY

Material: PVC

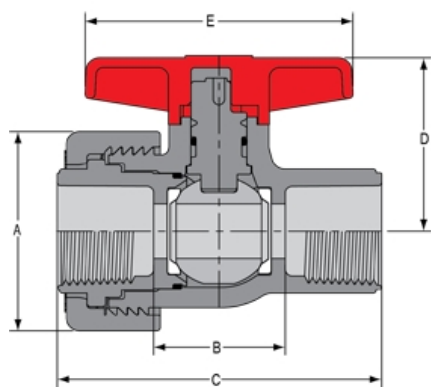

Type Single Entry
Connection Fipt
O-Ring Buna-N
Pressure Rating 235 psi @ 73° F
Color Gray

A = 1-15/16

B = 1- 5/8

C = 3- 1/16

D = 1- 5/8

E = 2- 1/2

Cv = 38

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

