

Part No: 2411-040W

Valves

Single Entry Ball Valve

Desc: 4 PVC SE BALL VALVE THD BUNA

MSRP: 736.4

Part Code: 240

Weight(lbs): 10.013


Weight(kg): 4.542

Weight(gm): 4542

Size: 4"

Color: WHITE

Material: PVC

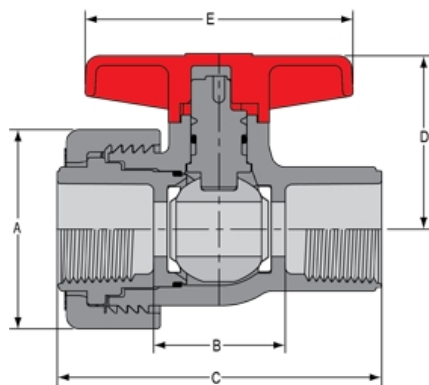

Type Single Entry
Connection Fipt
O-Ring Buna-N
Pressure Rating 150 psi @ 73° F
Color White

A = 7- 3/4

B = 6- 7/8

C = 9- 3/4

D = 6- 1/8

E = 9- 1/16

Cv = 3104

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

