

Part No: 2412-012G

Valves

Single Entry Ball Valve

Desc: 1-1/4 PVC SE BALL VALVE SOC BUNA

MSRP: 72.19

Part Code: 240

Weight(lbs): 0.73


Weight(kg): 0.331

Weight(gm): 331

Size: 1-1/4"

Color: GRAY

Material: PVC

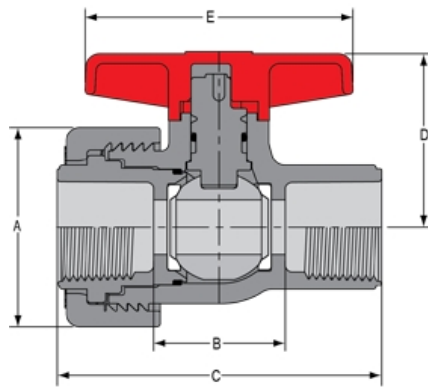

Type Single Entry
Connection Socket
O-Ring Buna-N
Pressure Rating 235 psi @ 73° F
Color Gray

A = 3- 1/8

B = 1-15/16

C = 4- 1/8

D = 2-13/16

E = 3- 1/2

Cv = 292

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

