

**Part No:** 2422-030G

**Valves**

**Single Entry Ball Valve**

**Desc:** 3 PVC SE BALL VALVE SOC EPDM

**MSRP:** 454.82

**Part Code:** 240

**Weight(lbs):** 5.163


**Weight(kg):** 2.342

**Weight(gm):** 2342

**Size:** 3"

**Color:** GRAY

**Material:** PVC

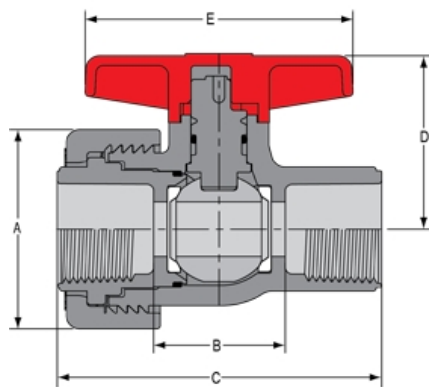

**Type** Single Entry  
**Connection** Socket  
**O-Ring** EPDM  
**Pressure Rating** 150 psi @ 73° F  
**Color** Gray

**A** = 6- 3/16

**B** = 4- 3/8

**C** = 8- 1/8

**D** = 5- 1/2

**E** = 7- 5/8

**Cv** = 1660

**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

