

**Part No:** 2432-010G

**Valves**

**Single Entry Ball Valve**

**Desc:** 1 PVC SE BALL VALVE SOC FKM

**MSRP:** 46.88

**Part Code:** 240

**Weight(lbs):** 0.503


**Weight(kg):** 0.228

**Weight(gm):** 228

**Size:** 1"

**Color:** GRAY

**Material:** PVC

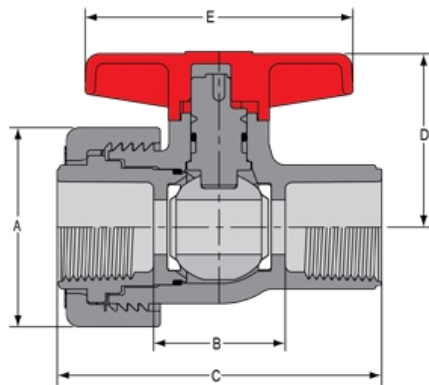

**Type** Single Entry  
**Connection** Socket  
**O-Ring** FKM  
**Pressure Rating** 235 psi @ 73° F  
**Color** Gray

**A** = 2- 5/8

**B** = 1- 5/8

**C** = 3- 7/8

**D** = 2- 5/16

**E** = 3-15/16

**Cv** = 146

**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

