

Part No: 2621-020C

Valves

Utility Ball Valve

Desc: 2 CPVC UTILITY BALL VALVE FPT EPDM

MSRP: 77.86

Part Code: 216

Weight(lbs): 1.371


Weight(kg): 0.622

Weight(gm): 622

Size: 2"

Color: GRAY

Material: CPVC

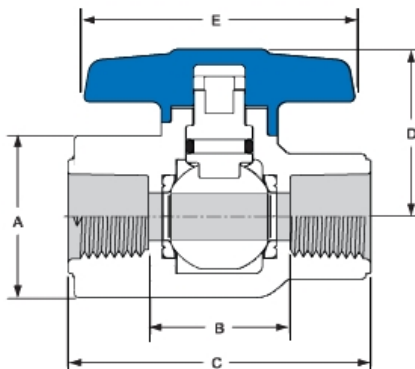

Type Utility
Connection Fipt
O-Ring EPDM
Pressure Rating 150 psi @ 73° F
Color Gray

A = 3-9/16

B = 2-13/16

C = 5-1/8

D = 3-7/8

E = 5

Cv = 755

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

