

Part No: 2622-012C

Valves

Utility Ball Valve

Desc: 1-1/4 CPVC UTILITY BALL VALVE SOC EPDM

MSRP: 40.33

Part Code: 216

Weight(lbs): 0.591


Weight(kg): 0.268

Weight(gm): 268

Size: 1-1/4"

Color: GRAY

Material: CPVC

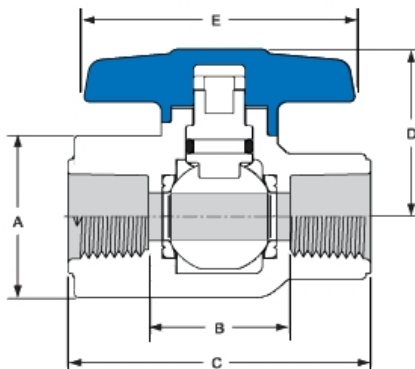

Type Utility
Connection Socket
O-Ring EPDM
Pressure Rating 150 psi @ 73° F
Color Gray

A = 2- 9/16

B = 1-7/8

C = 3-13/16

D = 2-13/16

E = 3- 3/4

Cv = 306

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

