

Part No: 2721T-012CSR

Valves

Diaphragm Valve

Desc: 1-1/4 CPVC DIAPHRGM VLV SR/THD PTFE/EPDM

MSRP: 1094.33

Part Code: 272

Weight(lbs): 3.536


Weight(kg): 1.604

Weight(gm): 1604

Size: 1-1/4"

Color: GRAY

Material: CPVC

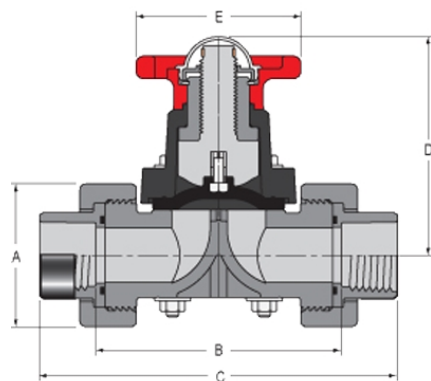

Connection SR Fipt

O-Ring EPDM

Diaphragm Material PTFE/EPDM

A = 3- 5/16

B = 5- 1/2

C = 8- 1/4

D = 5- 5/8

E = 3- 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

