

Part No: 2721T-015CSR

Valves

Diaphragm Valve

Desc: 1-1/2 CPVC DIAPHRGM VLV SR/THD PTFE/EPDM

MSRP: 1111.34

Part Code: 272

Weight(lbs): 3.728


Weight(kg): 1.691

Weight(gm): 1691

Size: 1-1/2"

Color: GRAY

Material: CPVC

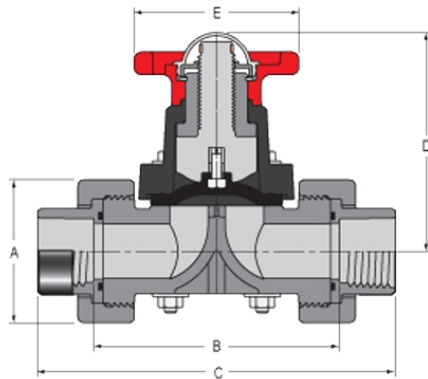

Connection SR Fipt

O-Ring EPDM

Diaphragm Material PTFE/EPDM

A = 3-17/32

B = 6-5/16

C = 8-7/16

D = 5-5/8

E = 4-5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

