

Part No: 2723-080P

Valves

Diaphragm Valve

Desc: 8 GFPP DIAPHRAGM VALVE FLANGED EPDM

MSRP: 11236.32

Part Code: 281

Weight(lbs): 72.043


Weight(kg): 32.678

Weight(gm): 32678

Size: 8

Color: BEIGE

Material: Polypropylene

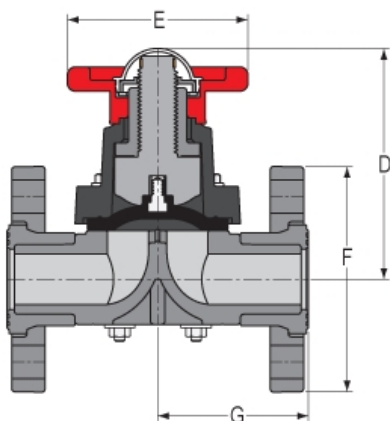

Connection Flanged
Diaphragm Material EPDM

D = 24-25/32

E = 16

F = 13- 1/2

G = 11-15/64

No of Bolts = 8

Bolt Circle Dia. = 11- 3/4

Bolt Size = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

