

Part No: 2731VT-007CSR

Valves

Diaphragm Valve

Desc: 3/4 CPVC DPHRGM VLV PTFE/FKM SR/THD FKM

MSRP: 754.03

Part Code: 272

Weight(lbs): 1.235


Weight(kg): 0.56

Weight(gm): 560

Size: 3/4"

Color: GRAY

Material: CPVC

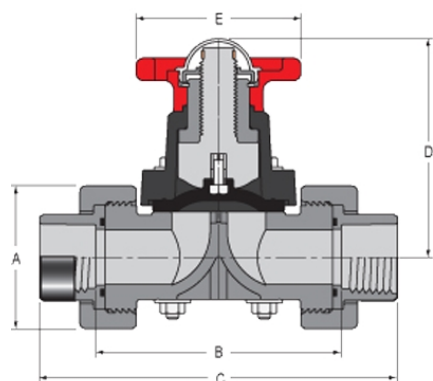

Connection SR Fipt

O-Ring FKM

Diaphragm Material PTFE/FKM

A = 2- 1/2

B = 4- 1/2

C = 5-15/16

D = 3- 3/4

E = 3- 1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

