

Part No: 2733-005C

Valves

Diaphragm Valve

Desc: 1/2 CPVC DIAPHRAGM VALVE FLANGED FKM

MSRP: 548.58

Part Code: 272

Weight(lbs): 1.08


Weight(kg): 0.49

Weight(gm): 490

Size: 1/2"

Color: GRAY

Material: CPVC

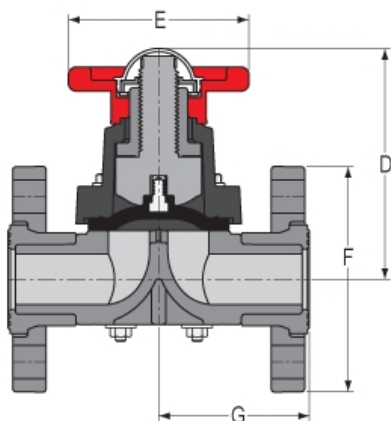

Connection Flanged
Diaphragm Material FKM

D = 3-11/32

E = 2- 7/8

F = 3- 1/2

G = 2- 9/16

No of Bolts = 4

Bolt Circle Dia. = 2- 3/8

Bolt Size = 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

