

**Part No:** 2733-060

**Valves**

**Diaphragm Valve**

**Desc:** 6 PVC DIAPHRAGM VALVE FLANGED FKM

**MSRP:** 5600.57

**Part Code:** 271

**Weight(lbs):** 57.649


**Weight(kg):** 26.149

**Weight(gm):** 26149

**Size:** 6"

**Color:** GRAY

**Material:** PVC

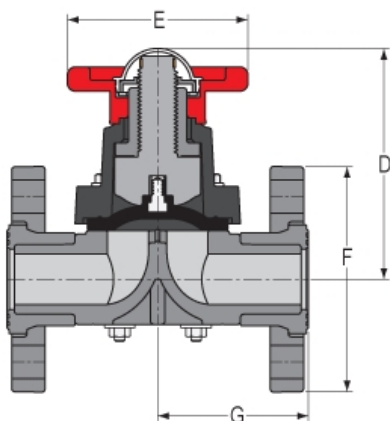

**Connection** Flanged  
**Diaphragm Material** FKM

**D** = 20

**E** = 16

**F** = 11- 1/4

**G** = 9-13/32

**No of Bolts** = 8

**Bolt Circle Dia.** = 9- 1/2

**Bolt Size** = 3/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

