

**Part No:** 2737-005C

**Valves**

**Diaphragm Valve**

**Desc:** 1/2 CPVC DIAPHRAGM VALVE SPIGOT FKM

**MSRP:** 509.97

**Part Code:** 272

**Weight(lbs):** 0.683


**Weight(kg):** 0.31

**Weight(gm):** 310

**Size:** 1/2"

**Color:** GRAY

**Material:** CPVC

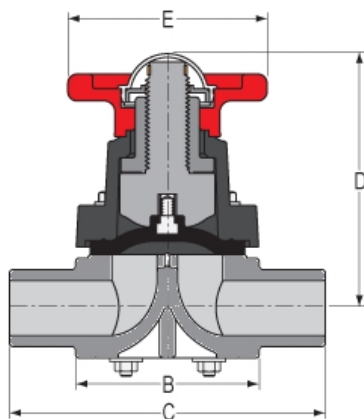

**Connection** Spigot  
**Diaphragm** FKM  
**Material**

**B** = 2- 5/8

**C** = 4- 7/8

**D** = 3-11/32

**E** = 2- 7/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

