

**Part No:** 2737-012C

**Valves**

**Diaphragm Valve**

**Desc:** 1-1/4 CPVC DIAPHRAGM VALVE SPIGOT FKM

**MSRP:** 917.27

**Part Code:** 272

**Weight(lbs):** 2.734


**Weight(kg):** 1.24

**Weight(gm):** 1240

**Size:** 1-1/4"

**Color:** GRAY

**Material:** CPVC

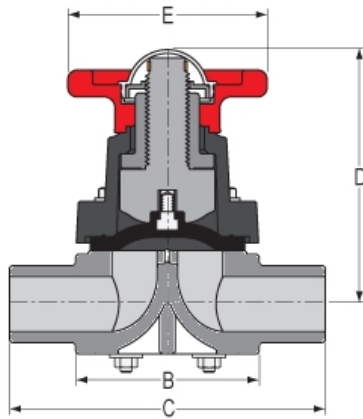

**Connection** Spigot  
**Diaphragm** FKM  
**Material**

**B** = 3- 3/4

**C** = 6- 1/4

**D** = 5- 5/8

**E** = 4- 19/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

