

**Part No:** 2739-015C

**Valves**

**Diaphragm Valve**

**Desc:** 1-1/2 CPVC DIAPHRAGM VALVE SOC/FPT FKM

**MSRP:** 954.71

**Part Code:** 272

**Weight(lbs):** 4.09


**Weight(kg):** 1.855

**Weight(gm):** 1855

**Size:** 1-1/2"

**Color:** GRAY

**Material:** CPVC

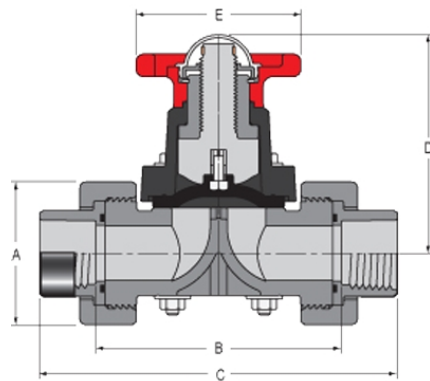

**Connection** Socket + Fipt

**O-Ring** FKM

**Diaphragm Material** FKM

**A** = 3-17/32

**B** = 6-5/16

**C** = 8-7/16

**D** = 5-5/8

**E** = 4-5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

