

**Part No:** 2739T-005

**Valves**

**Diaphragm Valve**

**Desc:** 1/2 PVC DPHGMVLV SOC/FPT FKM PTFE/EPDM

**MSRP:** 410.4

**Part Code:** 270

**Weight(lbs):** 0.917


**Weight(kg):** 0.416

**Weight(gm):** 416

**Size:** 1/2"

**Color:** GRAY

**Material:** PVC

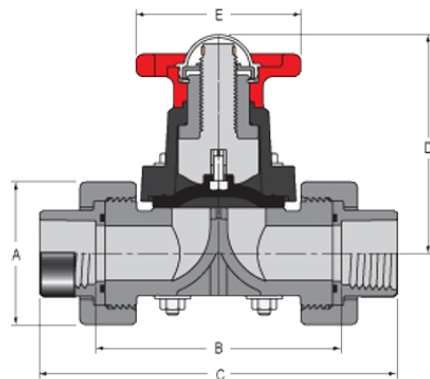

**Connection** Socket + Fipt

**O-Ring** FKM

**Diaphragm Material** PTFE/EPDM

**A** = 1-15/16

**B** = 3- 7/8

**C** = 5- 3/16

**D** = 3-11/32

**E** = 2- 7/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

