

Part No: 2739T-007C

Valves

Diaphragm Valve

Desc: 3/4 CPVC DPHGM VLV SOC/FPT FKM PTFE/EPDM

MSRP: 681.74

Part Code: 272

Weight(lbs): 1.288


Weight(kg): 0.584

Weight(gm): 584

Size: 3/4"

Color: GRAY

Material: CPVC

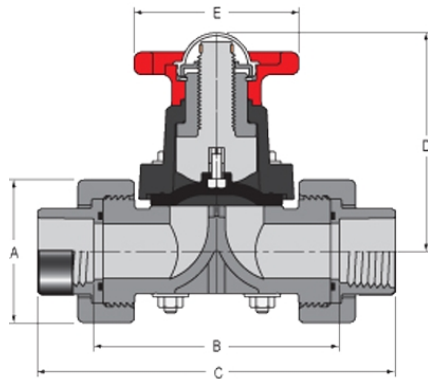

Connection Socket + Fipt

O-Ring FKM

Diaphragm Material PTFE/EPDM

A = 2- 1/2

B = 4- 1/2

C = 5-15/16

D = 3- 3/4

E = 3- 1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

