

Part No: 2793T-015C

Valves

Diaphragm Valve

Desc: 1-1/2 CPVC DIAPHRAGM FLANGED PTFE/EPDM

MSRP: 1418.48

Part Code: 272

Weight(lbs): 3.926


Weight(kg): 1.781

Weight(gm): 1781

Size: 1-1/2"

Color: GRAY

Material: CPVC

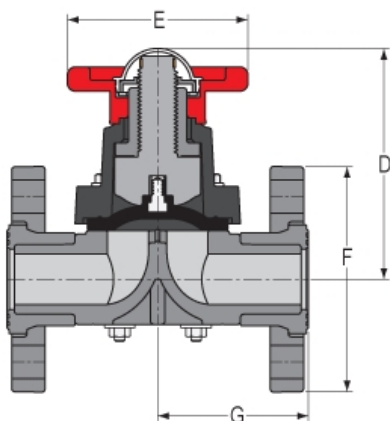

Connection Flanged
Diaphragm Material PTFE/EPDM

D = 5- 5/8

E = 4-19/32

F = 5

G = 3- 3/8

No of Bolts = 4

Bolt Circle Dia. = 3- 7/8

Bolt Size = 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

