

**Part No:** 2793T-020C

**Valves**

**Diaphragm Valve**

**Desc:** 2 CPVC DIAPRAHGM VALVE FLANGED PTFE/EPDM

**MSRP:** 1576.11

**Part Code:** 272

**Weight(lbs):** 6.149


**Weight(kg):** 2.789

**Weight(gm):** 2789

**Size:** 2"

**Color:** GRAY

**Material:** CPVC

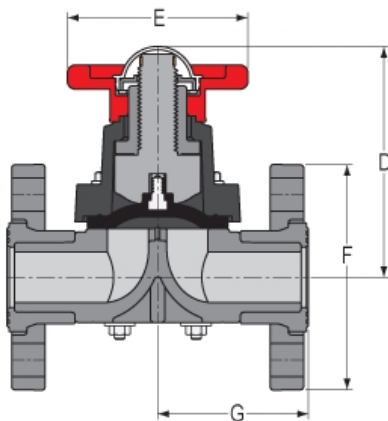

**D = 7**

**E = 5- 7/8**

**F = 6**

**G = 4**

**No of Bolts = 4**

**Bolt = 4- 3/4  
Circle  
Dia.**

**Bolt Size = 5/8**

**Connection** Flanged

**Diaphragm Material** PTFE/EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

