

**Part No:** 2793T-060C

**Valves**

**Diaphragm Valve**

**Desc:** 6 CPVC DIAPHRAGM VALVE FLANGED PTFE/EPDM

**MSRP:** 11961.37

**Part Code:** 273

**Weight(lbs):** 58.032


**Weight(kg):** 26.323

**Weight(gm):** 26323

**Size:** 6"

**Color:** GRAY

**Material:** CPVC

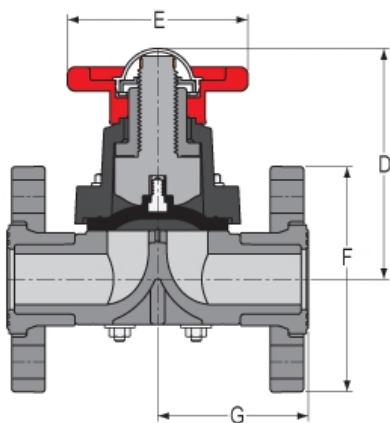

**Connection** Flanged  
**Diaphragm Material** PTFE/EPDM

**D** = 20      **Bolt Size** = 3/4      **E** = 16      **F** = 11- 1/4      **G** = 9-13/32  
**No of Bolts** = 8      **Bolt Circle Dia.** = 9- 1/2

## Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch
- L** = Overall length of fittings;  $\pm 1/16$  inch.
- M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.
- N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.
- W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

