

Part No: 2793T-080C

Valves

Diaphragm Valve

Desc: 8 CPVC DIAPHRAGM VALVE FLANGED PTFE/EPDM

MSRP: 17837.98

Part Code: 273

Weight(lbs): 89.567


Weight(kg): 40.627

Weight(gm): 40627

Size: 8"

Color: GRAY

Material: CPVC

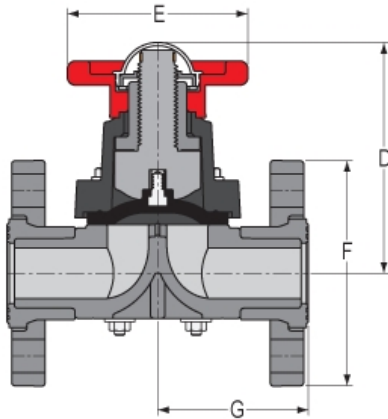

Connection Flanged
Diaphragm Material PTFE/EPDM

D = 24-25/32

E = 16

F = 13- 1/2

G = 11-15/64

No of Bolts = 8

Bolt Circle Dia. = 11- 3/4

Bolt Size = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

