

Part No: 2793VT-025C

Valves

Diaphragm Valve

Desc: 2-1/2 CPVC DPHRGM VALVE FLANGED PTFE/FKM

MSRP: 3678.98

Part Code: 273

Weight(lbs): 19.021


Weight(kg): 8.628

Weight(gm): 8628

Size: 2-1/2"

Color: GRAY

Material: CPVC

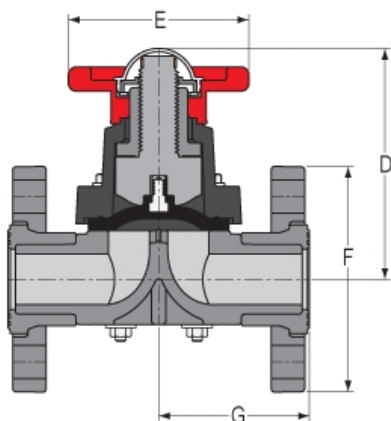

Connection Flanged
Diaphragm Material PTFE/FKM

D = 10-3/4

E = 11-1/8

F = 7-7/16

G = 5-5/8

No of Bolts = 4

Bolt Circle Dia. = 5- 1/2

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

