

Part No: 2793VT-040P

Valves

Diaphragm Valve

Desc: 4 GFPP DPHRAGM VALVE FLANGED PTFE/FKM

MSRP: 3677.03

Part Code: 281

Weight(lbs): 22.075


Weight(kg): 10.013

Weight(gm): 10013

Size: 4

Color: BEIGE

Material: Polypropylene

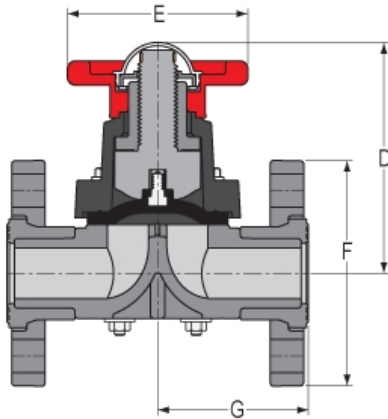

Connection Flanged
Diaphragm Material PTFE/FKM

Bolt Size = 5/8

D = 12- 3/4

E = 13- 3/16

F = 9

G = 6-23/32

No of Bolts = 8

Bolt Circle Dia. = 7- 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

