

Part No: 280-100704

Fabricated Low Head PIP

Elbows

Desc: 10 PVC 60 ELL SOC LOW HEAD PIP

MSRP: 231.01

Part Code: 300

Weight(lbs): 4.343

Weight(kg): 1.97

Weight(gm): 1970


Size: 10

Color: WHITE

Material: PVC

Connection Socket x Socket

Angle 60°

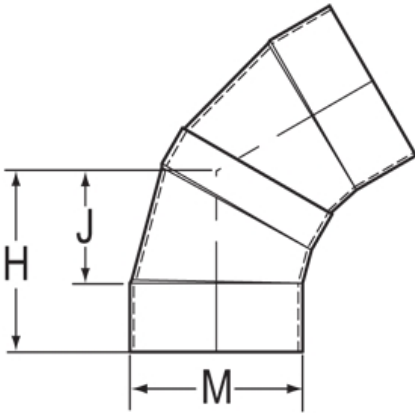

H = 10-3/8

J = 6-3/8

M = 10-7/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

