

Part No: 280-101650

Fabricated Low Head PIP

Adapters

Desc: 8 PVC ADAPTER SOC LOW HEAD IPSXPIP

MSRP: 72.37

Part Code: 300

Weight(lbs): 2.271

Weight(kg): 1.03

Weight(gm): 1030


Size: 8

Color: WHITE

Material: PVC

Type IPS x PIP Adapter

Connection Socket x Socket

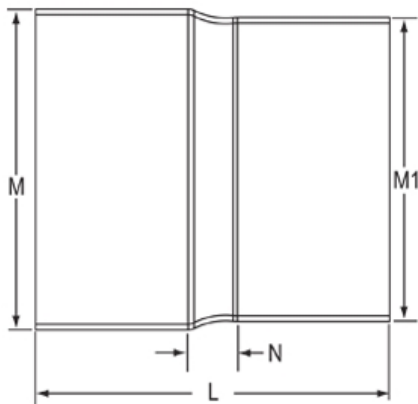

L = 9-7/8

M = 8-15/16

M1 = 8-1/2

N = 1-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

