

Part No: 280-101792

Fabricated Low Head PIP

Saddles

Desc: 12X2 PVC SADDLE SOC LOW HEAD PIPXIPS

MSRP: 31.29

Part Code: 300

Weight(lbs): 0.529

Weight(kg): 0.24

Weight(gm): 240


Size: 12 X 2

Color: WHITE

Material: PVC

Type Saddle-Reducer

Connection Socket

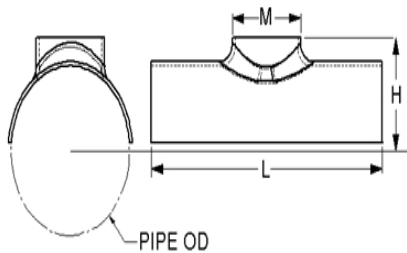

H = 6-15/16

L = 8-3/4

M = 2-5/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

