

Part No: 280-101818

Fabricated Low Head PIP

Saddles

Desc: 12X8 PVC SADDLE SOC LOW HEAD PIP

MSRP: 54.8

Part Code: 300

Weight(lbs): 1.488

Weight(kg): 0.675

Weight(gm): 675


Size: 12 X 8

Color: WHITE

Material: PVC

Type Saddle-Reducer

Connection Socket

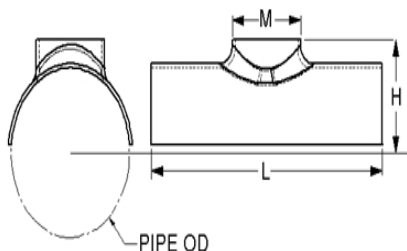

H = 7-5/8

L = 13-1/2

M = 8-7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

